



HIGH PERFORMANCE 1-DRIVE NETWORK STORAGE

LinkStation™ Pro is a high performance 1-drive network storage device that comes equipped with a whole host of features, perfect for storing, sharing, serving and protecting your most important data. Equipped with a high performance 1.6 GHz processor and DDR3 RAM, LinkStation Pro boasts transfer speeds up to 76 MB/s, nearly twice as fast as a standard USB drive. Backup multiple PCs and Mac® computers simultaneously and enjoy uninterrupted access to terabytes of storage on your network and even over the Internet while away from home.

FEATURES

SECURE CENTRAL STORAGE

With terabytes of storage, LinkStation Pro provides a reliable, central location to store and protect all data from every PC and Mac® computer, tablet device and smartphone in your home or small office. Store, access and share files from anywhere over your wireless network at speeds up to twice as fast as a standard USB hard drive.

EXCEPTIONAL PERFORMANCE

Equipped with a high performance 1.6 GHz processor and DDR3 RAM, LinkStation Pro offers much more than simple home shared storage. This single drive network storage device boasts transfer speeds up to 76 MB/s, nearly twice as fast as a standard USB

STREAM YOUR FAVORITE MEDIA

LinkStation Pro is DLNA Certified, supports Squeezebox and can be used as an iTunes server to stream all of your favorite music, movies and shows to multiple devices simultaneously.

EASY SCHEDULED BACKUP

LinkStation Pro features NovaBACKUP® Professional for Windows® and Time Machine® support for Mac for whole home data backup. Disaster and hard drive failures happen unexpectedly; don't leave your important files and treasured memories in the hands of chance. Schedule backups for every computer in your house and easily protect all of your data, down to the very last byte.

MEDIA STORAGE CAPACITY

HDD Size↓	Photos*	Movies†	Songs‡
1 TB	450,000	1,000	250,000
2 TB	900,000	2,000	500,000
3 TB	1,350,000	3,000	750,000
4 TB	1,800,000	4,000	1,000,000

FREE PERSONAL CLOUD SERVICE

Buffalo's free WebAccess service allows you to create a personal cloud for easy remote access and file sharing with anyone, anywhere over the Internet. Your data remains securely stored in one place on your home network, but you can access it quickly from any computer, tablet or smartphone device over the Web.

For enhanced access on the go, download Buffalo's free WebAccess mobile apps.

WebAccess i for iPhone® and iPod® touch

WebAccess i HD for iPad®

WebAccess A for Android


Results will vary based on individual factors.

** Figures represent the average number of photos taken with a 10 megapixel camera with an average file size of 2.2 MB per photo.*

† Figures represent the number of movies based on an average file size of 1 GB per movie.

‡ Figures represent the number of MP3 files at an average length of 00:03:25/160 Kbps with an average file size of 4 MB per song.

1 MB = 1,000,000 bytes, 1 GB = 1,000,000,000 bytes, 1 TB = 1,000,000,000,000 bytes. Total accessible capacity varies depending on operating environment.

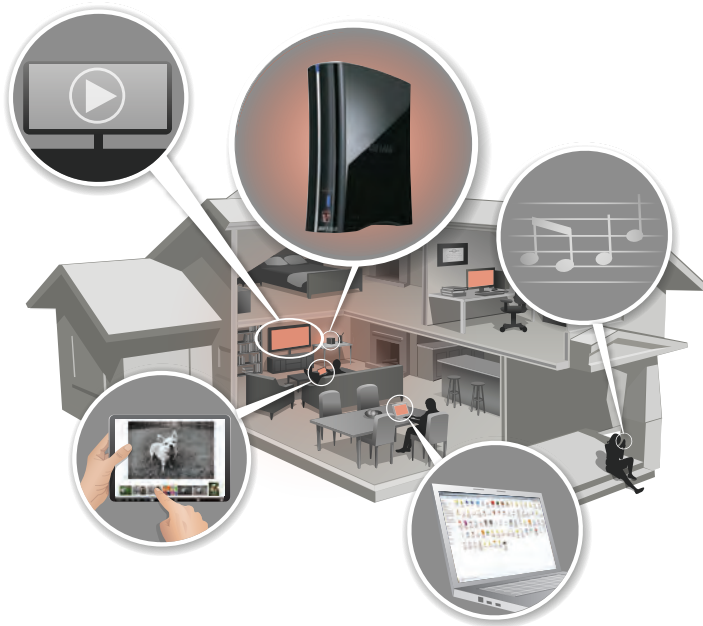

LINKSTATION NAS SYSTEM

LinkStation Pro runs on Buffalo's LinkStation NAS System, providing a host of useful features from network file sharing and security to RAID management, remote access and more. Included on all Buffalo LinkStation devices, LinkStation NAS System simplifies your everyday data needs.

MODELS

LS-V2.0TL, LS-V3.0TL, LS-V4.0TL

SPECIFICATIONS

INTERNAL HARD DRIVES

Number of Drives	1
Drive Interface	SATA 3 Gbps
Hard Drive Sizes:	2 TB, 3 TB, 4 TB
Total Hard Drive:	2 TB, 3 TB, 4 TB

LAN INTERFACE

Standard Compliance	IEEE802.3ab/IEEE802.3/IEEE802.3u Standard
---------------------	---

USB INTERFACE

Standard Compliance	USB 2.0
Connector Type	A type
Number of Ports	1
Data Transfer Rates	Max. 480 Mbps (High Speed mode)

PROTOCOL SUPPORT

Networking	TCP/IP
File Sharing	CIFS/SMB, AFP, HTTP/HTTPS, FTP
Management	HTTP/HTTPS
Time Synchronization	NTP

OTHER

Dimensions (W x H x D in)	1.78 x 6.89 x 6.15
Weight (lbs)	2.5
Power Consumption (Watts)	Average 17 W (with no USB devices connected)
Power Supply	AC 100-240V 50/60 Hz
Client OS Support	Windows [®] 8 (32-bit/64-bit), Windows [®] 7 (32-bit/64-bit), Windows Vista [®] (32-bit/64-bit), Windows [®] XP, Windows [®] 2000, Windows Server [®] 2003, Windows Server [®] 2008, Mac OS [®] X 10.5 - 10.8

*1 TB = 1,000,000,000,000 bytes; total accessible capacity varies depending on operating environment. Data rate, features and performance may vary based on the configuration of your system and other factors. Buffalo Technology (Buffalo Inc.) shall not be responsible for data loss and shall have no liability arising out of damages from lost data.

Box Contents

LinkStation Pro LS-VL
Setup CD-ROM
Quick-Setup Guide
Ethernet Cable
AC Adapter
Warranty Statement

24/7 TECH SUPPORT | 1 YEAR WARRANTY

(866) 752-6210 | USA & Canada Only

©2013 BUFFALO INC. All rights reserved. BUFFALO and BUFFALO logo are either trademarks or registered trademarks of MELCO HOLDINGS INC. LinkStation and LinkStation logo are either trademarks or registered trademarks of BUFFALO INC. or its affiliates in the United States and other countries. BitTorrent and BitTorrent logo are trademarks of BitTorrent, Inc. in the United States and other countries. DLNA Certified and DLNA Certified logo are either trademarks or registered trademarks of the Digital Living Network Alliance in the United States and other countries. Mac, Mac OS, iPhone and Time Machine are registered trademarks or Apple Inc. in the United States and other countries. NovaBACKUP and NovaStor logo are either trademarks or registered trademarks of NovaStor Corporation in the United States and other countries. UPnP is either a trademark or registered trademark of the UPnP Forum in the United States and other countries. Windows and Windows logo are registered trademarks of Microsoft Corporation in the United States and/or other countries. The names and logos of other companies mentioned herein belong to their respective owners.