



THUNDERBOLT SSD STORAGE

DUAL-DRIVE, RAID-ENABLED



DriveStation™ Mini Thunderbolt SSD is an easy to use, ultra high performance storage solution featuring two RAID enabled SSDs and dual 10 Gb/s Thunderbolt ports. With blazing fast transfer speeds up to 763 MB/s, it is up to 4.5x faster than USB 3.0 hard drives and 19x faster than USB 2.0 hard drives. Perfect for any Mac® computer with Thunderbolt support, its dual Thunderbolt ports support daisy chaining up to six supported peripherals, offering bidirectional channels for simultaneous data and video transfers without compromising bandwidth. Additionally, DriveStation Mini Thunderbolt SSD features two RAID 0/1 enabled SSDs that can be configured for automatic data protection or maximum capacity and performance. With high performance operation, unique streamlining features and revolutionary Thunderbolt connectivity, DriveStation Mini Thunderbolt SSD is the ideal storage solution for creative professionals and power-users who want maximum performance and flexibility.

FEATURES


ULTRA FAST SSD

DriveStation Mini Thunderbolt SSD features two high speed SATA III SSDs for superior performance compared to standard hard drives, perfect for photo and video professionals creating large amounts of content.

REVOLUTIONARY THUNDERBOLT

DriveStation Mini Thunderbolt SSD features Thunderbolt technology, raising the bar on how you transfer, store and transport data. Delivering interface speeds up to 10 Gbps, it is the fastest interface available, **2X FASTER** than USB 3.0, ideal for creative professionals and multimedia enthusiasts. Additionally, you can daisy-chain up to six Thunderbolt devices to maximize the use of a single port on your Mac.

Ultra-fast Transfer Speeds

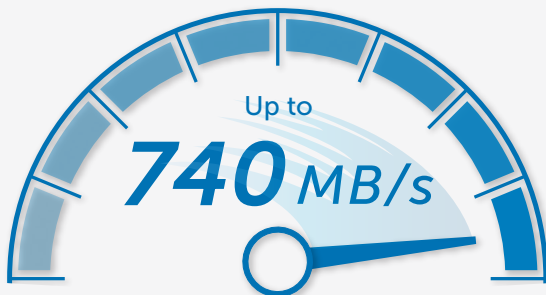

IDEAL FOR CONTENT CREATION

DriveStation Mini Thunderbolt SSD offers extreme performance for creative professionals using content creation programs who require the absolute best transfer performance.

DAISY CHAIN DEVICES

Thunderbolt technology allows users to daisy chain up to six devices from a single Thunderbolt connection on your computer. Daisy chain multiple DriveStation Mini Thunderbolt SSD units for an ultra fast, high capacity storage solution, ideal for creative professionals who need reliable, high speed access to their work.

EASY TO USE STORAGE

DriveStation Mini Thunderbolt SSD provides a reliable, easy to use storage for your Mac. Quickly expand the capacity of your computer for your favorite music, photos, videos and more. The Thunderbolt interface offers high speed performance and allows users to daisy chain up to six devices.

AUTOMATIC DATA PROTECTION

DriveStation Mini Thunderbolt SSD provides users the flexibility to easily maximize capacity or protect their data using RAID redundancy.

- RAID 0 offers optimal performance and capacity by evenly storing data across both hard drives with zero redundancy
- RAID 1 automatically creates an exact copy on the second hard drive, protecting your data from hard drive failure

THUNDERBOLT CABLE INCLUDED


DriveStation Mini Thunderbolt SSD is a complete storage solution, supplied with a Thunderbolt cable. Simply plug it in to any available Thunderbolt port on your Mac.

**\$50
VALUE**





DAISY CHAIN UP TO 6 DEVICES

Two Thunderbolt Ports Offer Maximum Workflow and Efficiency

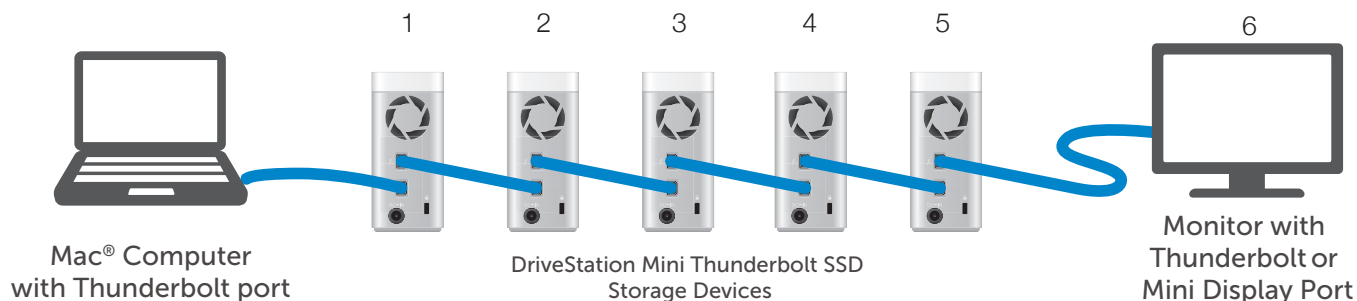

UP TO 19X FASTER FILE ACCESS!

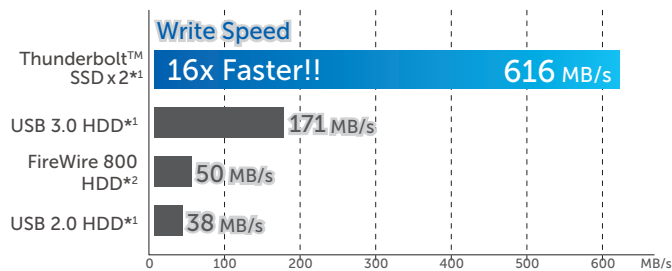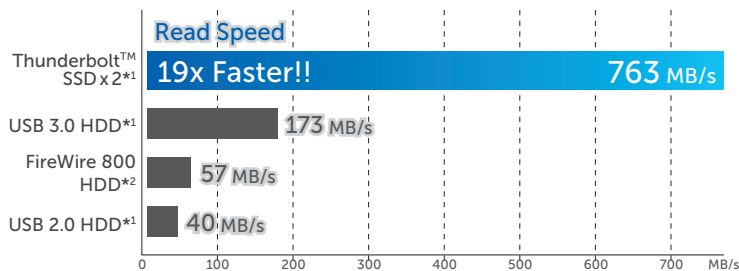

Test Environment: *1 MacBook® Pro (MC975J/A), Mac OS® X 10.8.2, Intel Core i7 2.3GHz, DDR3 8GB 1600MHz

*2 iMac 27inch (MC813J/A), MacOS X 10.8.2, Intel Core i5 2.7GHz, DDR3 4GB 1333MHz

MODELS

SSD-WA256T, SSD-WA512T, SSD-WA1.0T

BOX CONTENTS

DriveStation Mini Thunderbolt SSD, Thunderbolt Cable, AC Adapter, Quick-Setup Guide, Warranty Statement

SPECIFICATIONS

INTERNAL DRIVES

Number of Drives	2 x SSD
Drive Interface	SATA 3 Gbps
SSD Sizes:	128 GB, 256 GB, 500 GB
Total Capacity:	256 GB, 512 GB, 1 TB

INTERFACE

Standard Compliance	Thunderbolt
Number of Ports	2
Data Transfer Rate	Max 10 Gbps

OTHER

Dimensions (W x H x D)	1.77 x 4.02 x 6.06 in
Weight	1.19 lbs
Operating Environment (non-condensing)	41-95°F, 20 - 80% humidity
Power Supply	AC 100-240V 50/60Hz
Power Consumption	Max 24 W (Max 48 W w/ daisy chain)
Client OS Support	Mac OS® X 10.6 or later

24/7 TECH SUPPORT | 3 YEAR WARRANTY

(866) 752-6210 | USA & Canada Only

*1 TB = 1,000,000,000,000 bytes; total accessible capacity varies depending on operating environment. Data rate, features and performance may vary based on the configuration of your system and other factors. Buffalo Technology (Buffalo Inc.) shall not be responsible for data loss and shall have no liability arising out of damages from lost data.

©2013 BUFFALO INC. All rights reserved. BUFFALO and BUFFALO logo are either trademarks or registered trademarks of MELCO HOLDINGS INC. AirStation and AirStation logo are either trademarks or registered trademarks of BUFFALO INC. The names and logos of other companies mentioned herein belong to their respective owners.

www.BuffaloAmericas.com