




On Line Catalog

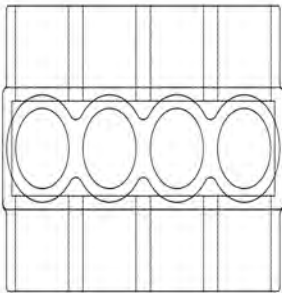

BURNDY Catalog Number
UPC Number
Description
Status

BIBD2/010
781810232729
2/0-14 2-SIDED-10 UNITAP
Active

Web Use
BURNDY Product Line

Width (in)
Hex Size (Key)
Length (in)
Height (in)

Dimensional

1.56
3/16
6.89
1.38

Min Voltage Rating

600

Number of Ports
Number of Screws

Electrical

600

General

10
10
Aluminum Multiple Tap
Connector, Clear Insulated, 10
Port, 2 Sided Entry, 14-2/0 AWG,
Al/Cu Rated

Product Description

Aluminum Size (Range)
Copper Solid Size (Range)
Copper Stranded (Range)

Conductor(s)

8 AWG-2/0 AWG
N/A
14 AWG-2/0 Str

Type of Hardware
Type of Plating
Insulation Type
Plated (Yes or No)
Product Material

Physical

Aluminum
Unplated
Plastisol
N
Aluminum

Rated for Direct Burial
UL Listed
CSA Certified
ROHS Compatible
UL Recognized
CULUS
Industry Standards

Approvals / Certifications

N
Y
Y
Compliant
N
N
UL468A-468B

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
Manchester NH03109

BURNDY Technical Servcies

47, industrial Park Drive
Manchester NH03109

Hours: 8.00 AM - 5.00 PM
Monday - Friday
Phone: 000-346-4175