




On Line Catalog

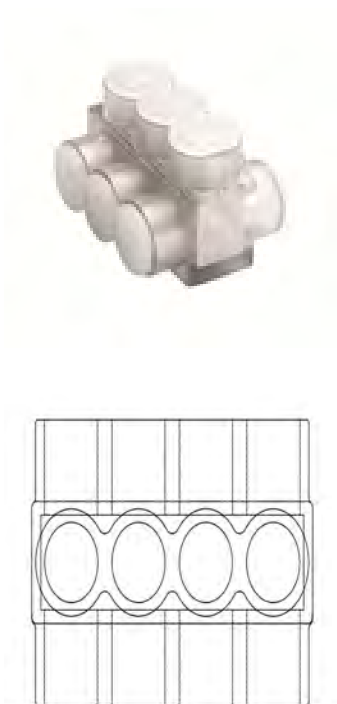

BURNDY Catalog Number
UPC Number
Description
Status

BIBD2/06
781810223970
2/0-14 TWO SIDED UNITAP
Active

Web Use
BURNDY Product Line

Width (in)
Hex Size (Key)
Length (in)
Height (in)

Dimensional

1.56
3/16
4.20
1.38

Min Voltage Rating

600

Number of Ports
Number of Screws

Electrical

600

General

6
6
Aluminum Multiple Tap
Connector, Clear Insulated, 6 Port,
2 Sided Entry, 14-2/0 AWG, Al/Cu
Rated

Product Description

Conductor(s)

Aluminum Size (Range)
Copper Solid Size (Range)
Copper Stranded (Range)

8 AWG-2/0 AWG
N/A
14 AWG-2/0 Str

Physical

Type of Hardware
Type of Plating
Insulation Type
Plated (Yes or No)
Product Material

Aluminum
Unplated
Plastisol
N
Aluminum

Approvals / Certifications

Rated for Direct Burial
UL Listed
CSA Certified
ROHS Compatible
UL Recognized
CULUS
Industry Standards

N
Y
Y
Compliant
N
N
UL468A-468B

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
Manchester NH03109

BURNDY Technical Servcies

47, industrial Park Drive
Manchester NH03109

Hours: 8.00 AM - 5.00 PM
Monday - Friday
Phone: 000-346-4175