




On Line Catalog

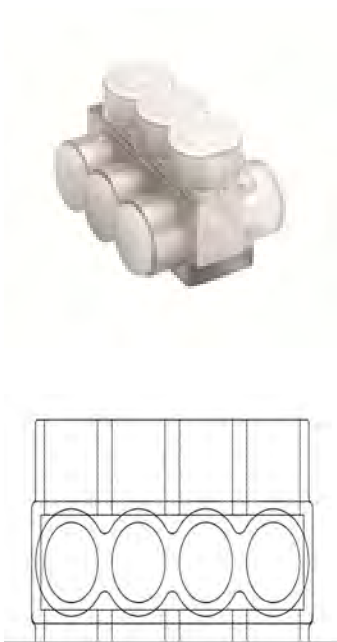

BURNDY Catalog Number
UPC Number
Description
Status

BIBD25012
781810232767
250-10 2-SIDED-12 UNITAP
Active

Web Use
BURNDY Product Line

Width (in)
Hex Size (Key)
Length (in)
Height (in)

Dimensional
2.64
5/16
11.41
2.13

Min Voltage Rating

Number of Ports
Number of Screws

Electrical
600
General
12
12

Product Description

Aluminum Multiple Tap
Connector, Clear Insulated, 12
Port, 2 Sided Entry, 10 AWG-250
kcmil, Al/Cu Rated

Aluminum Size (Range)
Copper Solid Size (Range)
Copper Stranded (Range)

Conductor(s)
8 AWG-250 kcmil
N/A
10 AWG-250 kcmil

Type of Hardware
Type of Plating
Insulation Type
Plated (Yes or No)
Product Material

Physical
Aluminum
Unplated
Plastisol
N
Aluminum

Rated for Direct Burial
UL Listed
CSA Certified
ROHS Compatible
UL Recognized
CULUS
Industry Standards

Approvals / Certifications
N
Y
Y
Compliant
N
N
UL468A-468B

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
Manchester NH03109

BURNDY Technical Servcies

47, industrial Park Drive
Manchester NH03109

Hours: 8.00 AM - 5.00 PM
Monday - Friday
Phone: 000-346-4175