




On Line Catalog

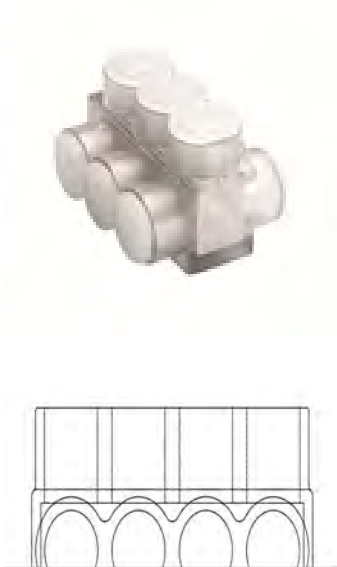

BURNDY Catalog Number	BIBD2506
UPC Number	781810133439
Description	250-10,2-SIDE, UNI-TAP
Status	Active

Web Use
BURNDY Product Line

Width (in)
Hex Size (Key)
Length (in)
Height (in)

Min Voltage Rating

Number of Ports
Number of Screws

Product Description

Aluminum Size (Range)
Copper Solid Size (Range)
Copper Stranded (Range)

Type of Hardware
Type of Plating
Insulation Type
Plated (Yes or No)
Product Material

Rated for Direct Burial
UL Listed
CSA Certified
ROHS Compatible
UL Recognized
CULUS
Industry Standards

Documentation

Dimensional

2.64
5/16
5.78
2.13

Electrical

600

General

6
6
Aluminum Multiple Tap
Connector, Clear Insulated, 6 Port,
2 Sided Entry, 10 AWG-250 kcmil,
Al/Cu Rated

Conductor(s)

8 AWG-250 kcmil
N/A
10 AWG-250 kcmil

Physical

Aluminum
Unplated
Plastisol
N
Aluminum

Approvals / Certifications

N
Y
Y
Compliant
N
N
UL468A-468B

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
Manchester NH03109

BURNDY Technical Servcies

47, industrial Park Drive
Manchester NH03109

Hours: 8.00 AM - 5.00 PM
Monday - Friday
Phone: 000-346-4175