




On Line Catalog

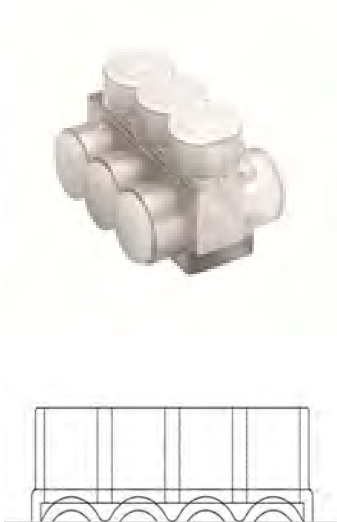

BURNDY Catalog Number	BIBD35010
UPC Number	781810232781
Description	350-10 2-SIDED-10 UNITAP
Status	Active
Web Use	
BURNDY Product Line	
	Dimensional
Width (in)	3.00
Hex Size (Key)	5/16
Length (in)	9.50
Height (in)	2.50
	Electrical
Min Voltage Rating	600
	General
Number of Ports	10
Number of Screws	10
Product Description	Aluminum Multiple Tap Connector, Clear Insulated, 10 Port, 2 Sided Entry, 10 AWG-350 kcmil, Al/Cu Rated
	Conductor(s)
Aluminum Size (Range)	8 AWG-350 kcmil
Copper Solid Size (Range)	N/A
Copper Stranded (Range)	10 AWG-350 kcmil
	Physical
Type of Hardware	Aluminum
Type of Plating	Unplated
Insulation Type	Plastisol
Plated (Yes or No)	N
Product Material	Aluminum
	Approvals / Certifications
Rated for Direct Burial	N
UL Listed	Y
CSA Certified	Y
ROHS Compatible	Compliant
UL Recognized	N
CULUS	N
Industry Standards	UL468A-468B
Documentation	

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
Manchester NH03109

BURNDY Technical Servcies

47, industrial Park Drive
Manchester NH03109

Hours: 8.00 AM - 5.00 PM
Monday - Friday
Phone: 000-346-4175