




On Line Catalog

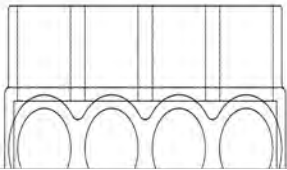

BURNDY Catalog Number
UPC Number
Description
Status

BIBD3505
 781810133460
 350-10, 2-SIDE, UNI-TAP
 Active

Web Use
 BURNDY Product Line

Width (in) 3.00
 Hex Size (Key) 5/16
 Length (in) 4.95
 Height (in) 2.50

Dimensional

Min Voltage Rating 600

Electrical

Number of Ports 5
 Number of Screws 5

General

Product Description

Aluminum Multiple Tap
 Connector, Clear Insulated, 5 Port,
 2 Sided Entry, 10 AWG-350 kcmil,
 Al/Cu Rated

Aluminum Size (Range)
 Copper Solid Size (Range)
 Copper Stranded (Range)

Conductor(s)

8 AWG-350 kcmil
 N/A
 10 AWG-350 kcmil

Type of Hardware
 Type of Plating
 Insulation Type
 Plated (Yes or No)
 Product Material

Physical

Aluminum
 Unplated
 Plastisol
 N
 Aluminum

Rated for Direct Burial
 UL Listed
 CSA Certified
 ROHS Compatible
 UL Recognized
 CULUS
 Industry Standards

Approvals / Certifications

N
 Y
 Y
 Compliant
 N
 N
 UL468A-468B

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
 Manchester NH03109

BURNDY Technical Services

47, industrial Park Drive
 Manchester NH03109

Hours: 8.00 AM - 5.00 PM

Monday - Friday

Phone: 000-346-4175