




On Line Catalog

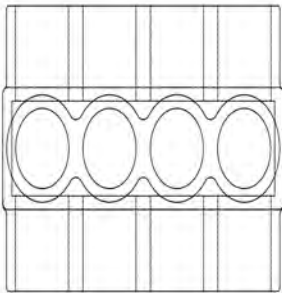

BURNDY Catalog Number
UPC Number
Description
Status

BIBD45
781810225684
14-4 TWO SIDED UNITAP
Active

Web Use
BURNDY Product Line

Screw Size
Width (in)
Hex Size (Key)
Length (in)
Height (in)

Min Voltage Rating

Number of Ports
Number of Screws

Dimensional
1/4
1.50
1/8
2.39
1.25

Electrical
600

General
5
5
Aluminum Multiple Tap
Connector, Clear Insulated, 5 Port,
2 Sided Entry, 14-4 AWG, Al/Cu
Rated

Product Description

Conductor(s)
8 AWG-4 AWG
N/A
14 AWG-4 Str

Aluminum Size (Range)
Copper Solid Size (Range)
Copper Stranded (Range)

Type of Hardware
Type of Plating
Insulation Type
Plated (Yes or No)
Product Material

Physical
Aluminum
Unplated
Plastisol
N
Aluminum

UL Listed
CSA Certified
Rated for Direct Burial
ROHS Compatible
UL Recognized
CULUS
Industry Standards

Approvals / Certifications
Y
Y
N
Compliant
N
N
UL468A-468B

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
Manchester NH03109

BURNDY Technical Servcies

47, industrial Park Drive
Manchester NH03109

Hours: 8.00 AM - 5.00 PM
Monday - Friday
Phone: 000-346-4175