




On Line Catalog

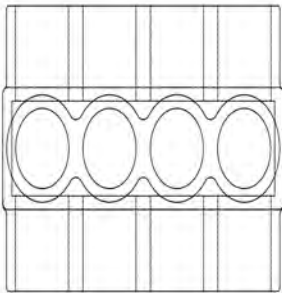

BURNDY Catalog Number
UPC Number
Description
Status

BIBD60010
781810232828
600-4 2-SIDED-10 UNITAP
Active

Web Use
BURNDY Product Line

Width (in)
Hex Size (Key)
Length (in)
Height (in)

Dimensional
3.00
3/8
12.97
2.75

Min Voltage Rating

Electrical
600

Number of Ports
Number of Screws

General
10
10
Aluminum Multiple Tap
Connector, Clear Insulated, 10
Port, 2 Sided Entry, 4 AWG-600
kcmil, Al/Cu Rated

Product Description

Aluminum Size (Range)
Copper Solid Size (Range)
Copper Stranded (Range)

Conductor(s)
4 AWG-600 kcmil
N/A
4 AWG-600 kcmil

Type of Hardware
Type of Plating
Insulation Type
Plated (Yes or No)
Product Material

Physical
Aluminum
Unplated
Plastisol
N
Aluminum

Rated for Direct Burial
UL Listed
CSA Certified
ROHS Compatible
UL Recognized
CULUS
Industry Standards

Approvals / Certifications
N
Y
Y
Compliant
N
N
UL468A-468B

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
Manchester NH03109

BURNDY Technical Servcies

47, industrial Park Drive
Manchester NH03109

Hours: 8.00 AM - 5.00 PM
Monday - Friday
Phone: 000-346-4175