




On Line Catalog

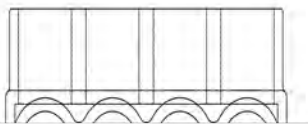

BURNDY Catalog Number
UPC Number
Description
Status

BIBD75010
 781810232903
 750-2 2-SIDED-10 UNITAP
 Active

Web Use
 BURNDY Product Line

Width (in) 3.38
 Hex Size (Key) 3/8
 Length (in) 13.87
 Height (in) 3.00

Dimensional

Min Voltage Rating

Electrical
 600

Number of Ports
 Number of Screws

General

10
 10
 Aluminum Multiple Tap
 Connector, Clear Insulated, 10
 Port, 2 Sided Entry, 2 AWG-750
 kcmil, Al/Cu Rated

Product Description

Conductor(s)

Aluminum Size (Range)
 Copper Solid Size (Range)
 Copper Stranded (Range)

2 AWG-750 kcmil
 N/A
 2 AWG-750 kcmil

Type of Hardware
 Type of Plating
 Insulation Type
 Plated (Yes or No)
 Product Material

Physical

Aluminum
 Unplated
 Plastisol
 N
 Aluminum

Approvals / Certifications

Rated for Direct Burial
 UL Listed
 CSA Certified
 ROHS Compatible
 UL Recognized
 CULUS
 Industry Standards

N
 N
 N
 Compliant
 N
 N
 UL468A-468B

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
 Manchester NH03109

BURNDY Technical Services

47, industrial Park Drive
 Manchester NH03109

Hours: 8.00 AM - 5.00 PM
 Monday - Friday
 Phone: 000-346-4175