




On Line Catalog



**BURNDY Catalog Number**  
**UPC Number**  
**Description**  
**Status**

GRF4C3  
 781810828021  
 UNIGROUND  
 Active

**Web Use**  
 BURNDY Product Line

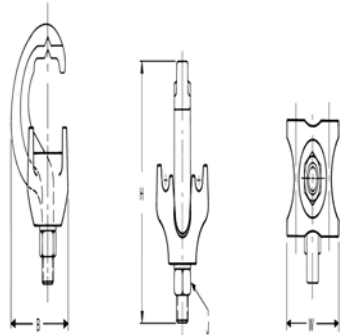

Width (in)  
 Height (in)  
 Size (Hex) or Size (Bolt)  
 Size (Hex) or Size (Bolt) - in  
 B Length (in)

**Dimensional**

1.76  
 3.14  
 3/8  
 0.38  
 1.96

Product Description

**General**

Univeral Grounding Clamp, 1 or 2  
 Nos of Conductors, 8 AWG-2  
 AWG, Pedestal Type : 1" (Round),  
 Upto 7/8" (Square), 3/8" Stud

Pedestal Type  
 Pipe, Tube, Rod Size (Range)  
 Copper Solid Size (Range)  
 Copper Stranded (Range)  
 Square Pipe or Tube Size (Range)

**Conductor(s)**

Round, Square  
 3/8 -1  
 8 AWG-2 AWG  
 8 AWG-2 AWG  
 1/2 -7/8

Installation Torque  
 Type of Plating  
 Plated (Yes or No)  
 Product Material

**Physical**

100  
 Tin - Electro Plated  
 Y  
 Copper Alloy

ROHS Compatible  
 UL Listed  
 CSA Certified  
 Rated for Direct Burial  
 UL Recognized  
 CULUS  
 Industry Standards

**Approvals / Certifications**

Exempt  
 Y  
 Y  
 N  
 N  
 N  
 UL467

**Documentation**

**For further technical assistance, please contact us**

**BURNDY LLC - USA**

47, industrial Park Drive  
 Manchester NH03109

**BURNDY Technical Servcies**

47, industrial Park Drive  
 Manchester NH03109

Hours: 8.00 AM - 5.00 PM  
 Monday - Friday  
 Phone: 000-346-4175