




On Line Catalog

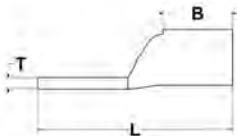

BURNDY Catalog Number
UPC Number
Description
Status

YA25LBOX
78181053251
1/0 CU 1-HOLE SHORT 5/16
Active

Web Use
BURNDY Product Line

Tongue Angle
Length (in)
Tongue Type
Barrell Style
Barrel Type
Thickness
B Length (in)
Pad Width (in)
Strip Length

Dimensional

Straight
1.96
Standard
Chamfered,Skived
Standard
0.12
0.88
0.75
15/16

Number of Holes

General

1
CU Compression Terminal Code
Conductor, Beveled Entry, 1
Hole/W/InspWindow,
1/0AWG(Code) 100(Navy), 600V-
35kV, 5/16" Stud, Standard
Barrel, Electro-Tin Plated

Product Description

Conductor(s)

Flex (Class G) Size - Range
Flex (Class H) Size - Range
Flex (Class I) Size - Range
Copper Solid Size (Range)
DLO Size (Range)
Copper Stranded (Range)

N/A
N/A
N/A
N/A
N/A
1/0

Type of Plating
Color Code
Plated (Yes or No)
Index Number
Product Material

Physical

Tin - Electro Plated
Pink
Y
12
Copper

Approvals / Certifications

UL Listed
CSA Certified
ROHS Compatible
UL Recognized
CULUS

Y
Y
Compliant
N
N

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
Manchester NH03109

BURNDY Technical Servcies

47, industrial Park Drive
Manchester NH03109

Hours: 8.00 AM - 5.00 PM
Monday - Friday
Phone: 000-346-4175