




[On Line Catalog](#)



BURNDY Catalog Number
UPC Number
Description
Status

YA28L2TC14E2
781810018248
CU HYDENT 4/0 STR.(2)1/4
Active

Web Use
BURNDY Product Line

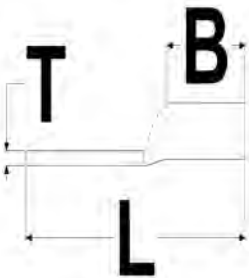

Tongue Angle
Length (in)
Tongue Type
Barrell Style
Bolt Hole Size (in)
Barrel Type
Thickness
B Length (in)
Pad Width (in)
E - in
Strip Length

Dimensional
Straight
2.78
Standard
Chamfered,Skived
0.27
Standard
0.14
0.88
1.02
0.75
1-1/8
General
2
Copper Compression Lug, 2 Hole
w/ Inspection Window, 4/0 AWG,
1/4" Stud, 3/4" Stud Hole
Spacing, Short Barrel, Tin Plated

Number of Holes

Product Description

Conductor(s)
N/A
N/A
N/A
N/A
N/A
N/A
4/0 AWG

Type of Plating
Color Code
Plated (Yes or No)
Index Number
Product Material

Physical
Tin - Electro Plated
Purple
Y
15
Copper

UL Listed
CSA Certified
ROHS Compatible
UL Recognized
CULUS
Industry Standards

Approvals / Certifications
Y
Y
Compliant
N
N
UL468A-468B

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
Manchester NH03109

BURNDY Technical Servcies

47, industrial Park Drive
Manchester NH03109

Hours: 8.00 AM - 5.00 PM
Monday - Friday
Phone: 000-346-4175