




[On Line Catalog](#)



BURNDY Catalog Number
UPC Number
Description
Status

YA29L2TC38
781810503676
CU HYDENT 250MCM (2) 3/8
Active

Web Use
BURNDY Product Line

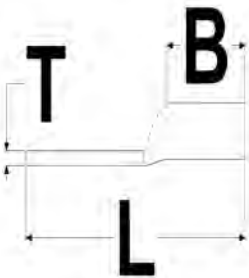

Tongue Angle
Length (in)
Tongue Type
Barrell Style
Bolt Hole Size (in)
Barrel Type
Thickness
B Length (in)
Pad Width (in)
E - in
Strip Length

Dimensional

Straight
3.43
Standard
Chamfered,Skived
0.39
Standard
0.16
1.06
1.10
1.00
1-1/8

Number of Holes

General

2
Copper Compression Lug, 2 Hole
w/ Inspection Window, 250 kcmil,
3/8" Stud, 1" Stud Hole Spacing,
Short Barrel, Tin Plated

Product Description

Conductor(s)

Flex (Class G) Size - Range
Flex (Class H) Size - Range
Flex (Class I) Size - Range
Copper Solid Size (Range)
DLO Size (Range)
Copper Stranded (Range)

N/A
N/A
N/A
N/A
N/A
250 kcmil

Physical

Type of Plating
Color Code
Plated (Yes or No)
Index Number
Product Material

Tin - Electro Plated
Yellow
Y
16
Copper

Approvals / Certifications

UL Listed
CSA Certified
ROHS Compatible
UL Recognized
CULUS
Industry Standards

Y
Y
Compliant
N
N
UL468A-468B

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
Manchester NH03109

BURNDY Technical Servcies

47, industrial Park Drive
Manchester NH03109

Hours: 8.00 AM - 5.00 PM
Monday - Friday
Phone: 000-346-4175