




On Line Catalog

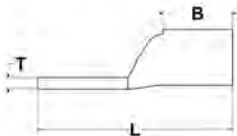

**BURNDY Catalog Number**  
**UPC Number**  
**Description**  
**Status**

YA29LBOX  
781810554500  
250 CU 1-HOLE SHORT 1/2  
Active

**Web Use**  
BURNDY Product Line

Tongue Angle  
Length (in)  
Tongue Type  
Barrell Style  
Bolt Hole Size (in)  
Barrel Type  
Thickness  
B Length (in)  
Pad Width (in)  
Strip Length

**Dimensional**  
Straight  
2.67  
Standard  
Chamfered,Skived  
0.52  
Standard  
0.16  
1.06  
1.11  
1-1/8

Number of Holes  
  
Product Description

**General**  
1  
Copper Compression Lug, 1 Hole  
w/ Inspection Window, 250 kcmil,  
1/2" Stud, Short Barrel, Tin Plated

Flex (Class G) Size - Range  
Flex (Class H) Size - Range  
Flex (Class I) Size - Range  
Copper Solid Size (Range)  
DLO Size (Range)  
Copper Stranded (Range)

**Conductor(s)**  
N/A  
N/A  
N/A  
N/A  
N/A  
250 kcmil

Type of Plating  
Color Code  
Plated (Yes or No)  
Index Number  
Product Material

**Physical**  
Tin - Electro Plated  
Yellow  
Y  
16  
Copper

UL Listed  
CSA Certified  
ROHS Compatible  
UL Recognized  
CULUS

**Approvals / Certifications**  
Y  
Y  
Compliant  
N  
N

**Documentation**

**For further technical assistance, please contact us**

**BURNDY LLC - USA**

47, industrial Park Drive  
Manchester NH03109

**BURNDY Technical Servcies**

47, industrial Park Drive  
Manchester NH03109

Hours: 8.00 AM - 5.00 PM  
Monday - Friday  
Phone: 000-346-4175