




On Line Catalog

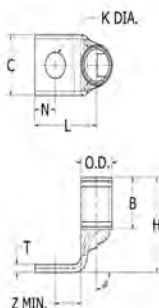

BURNDY Catalog Number
UPC Number
Description
Status

YA2CL490
781810019900
CU HYLUG-2 STR-3/8-90DEG
Active

Web Use
BURNDY Product Line

Tongue Angle
Length (in)
Tongue Type
Barrell Style
Bolt Hole Size (in)
Barrel Type
Thickness
B Length (in)
Pad Width (in)
Strip Length

Dimensional
90 Degree
1.14
Standard
Chamfered,Skived
0.39
Standard
0.11
0.88
0.60
15/16

Number of Holes

General
1
Cu Tubing Cu Hylug; 1 Hole with
Inspection Window; #2 AWG
Code,60 Navy; 600V-35kV; 3/8"
stud; Standard; Compression; 0.40
in BCD; Brown

Product Description

Flex (Class G) Size - Range
Flex (Class H) Size - Range
Flex (Class I) Size - Range
Copper Solid Size (Range)
DLO Size (Range)
Copper Stranded (Range)

Conductor(s)
N/A
N/A
N/A
N/A
N/A
2 AWG

Type of Plating
Bolt Hole Size
Color Code
Plated (Yes or No)
Index Number
Product Material

Physical
Tin - Electro Plated
3/8
Brown
Y
10
Copper

UL Listed
CSA Certified
ROHS Compatible
UL Recognized
CULUS
Industry Standards

Approvals / Certifications
Y
Y
Compliant
N
N
UL467

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
Manchester NH03109

BURNDY Technical Servcies

47, industrial Park Drive
Manchester NH03109

Hours: 8.00 AM - 5.00 PM
Monday - Friday
Phone: 000-346-4175