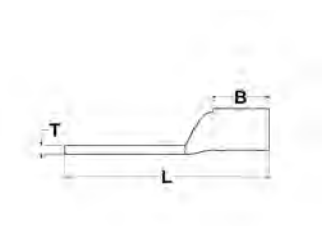



[On Line Catalog](#)


BURNDY Catalog Number
UPC Number
Description
Status

YA34L2TC12FX
 781810018989
 CULUG-350 FLEX-1/2X1-1/4
 Active

Web Use
 BURNDY Product Line

Dimensional

Tongue Angle
 Length (in)
 Tongue Type
 Barrell Style
 Bolt Hole Size (in)
 Barrel Type
 Thickness
 B Length (in)
 Pad Width (in)
 E - in
 Strip Length

Straight
 4.38
 Standard
 Chamfered
 0.52
 Standard
 0.23
 1.27
 1.55
 1.25
 1-5/16

General

Number of Holes
 Product Description

2
 Copper Compression Lug, 2 Hole
 w/ Inspection Window, 373.7 Flex,
 1/2" Stud, 1-1/4" Stud Hole
 Spacing, Short Barrel, Tin Plated

Conductor(s)

Flex (Class G) Size - Range
 Flex (Class H) Size - Range
 Flex (Class I) Size - Range
 Copper Solid Size (Range)
 DLO Size (Range)
 Copper Stranded (Range)

350 kcmil
 350 kcmil
 350 kcmil
 N/A
 373.7 (925/#24) DLO
 N/A

Physical

Type of Plating
 Bolt Hole Size
 Color Code
 Plated (Yes or No)
 Index Number
 Product Material

Tin
 1/2
 Blue
 Y
 19,470
 Copper

Approvals / Certifications

UL Listed
 CSA Certified
 ROHS Compatible
 UL Recognized
 CULUS

Y
 Y
 Compliant
 N
 N

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
 Manchester NH03109

BURNDY Technical Servcies

47, industrial Park Drive
 Manchester NH03109

Hours: 8.00 AM - 5.00 PM

Monday - Friday

Phone: 000-346-4175