




On Line Catalog

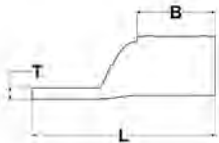

BURNDY Catalog Number
UPC Number
Description
Status

YA34LTC58FX
781810018972
CU. COMP. TERM. - 350 FL
Active

Web Use
BURNDY Product Line

Tongue Angle
Length (in)
Barrell Style
Bolt Hole Size (in)
Barrel Type
Thickness
B Length (in)
Pad Width (in)
Strip Length

Dimensional
Straight
3.37
Chamfered
0.66
Standard
0.23
1.27
1.55
1-5/16

Number of Holes

Product Description

General
1
Copper Compression Lug, 1 Hole
w/ Inspection Window, 350 Flex,
5/8" Stud, Short Barrel, Tin Plated

Flex (Class G) Size - Range
Flex (Class H) Size - Range
Flex (Class I) Size - Range
Copper Solid Size (Range)
DLO Size (Range)
Copper Stranded (Range)

Conductor(s)
350 kcmil
350 kcmil
350 kcmil
N/A
373.7 (925/#24) DLO
N/A

Type of Plating
Bolt Hole Size
Color Code
Plated (Yes or No)
Index Number
Product Material

Physical
Tin
5/8
Blue
Y
19,470
Copper

UL Listed
CSA Certified
ROHS Compatible
UL Recognized
CULUS

Approvals / Certifications
Y
Y
Compliant
N
N

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
Manchester NH03109

BURNDY Technical Servcies

47, industrial Park Drive
Manchester NH03109

Hours: 8.00 AM - 5.00 PM
Monday - Friday
Phone: 000-346-4175