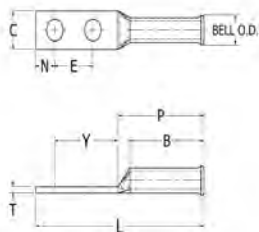



[On Line Catalog](#)


BURNDY Catalog Number
UPC Number
Description
Status

YA382TC38FXB
 781810059630
 BELLED HYLUG-500 FLEX-(2
 Active

Web Use
 BURNDY Product Line

Tongue Angle
 Length (in)
 Barrell Style
 Bolt Hole Size (in)
 Barrel Type
 Thickness
 B Length (in)
 Pad Width (in)
 E - in
 Strip Length

Dimensional

Straight
 6.01
 Belled
 0.39
 Long
 0.26
 3.08
 1.84
 1.00
 3-3/16

Number of Holes

General

2
 Copper Compression Lug, 2 Hole
 w/o Inspection Window, 535.3
 Flex, 3/8" Stud, 1" Stud Hole
 Spacing, Long Barrel, Belled End,
 Tin Plated

Product Description

Conductor(s)

Aircraft Cable Size (Range)
 Flex (Class H) Size - Range
 Flex (Class I) Size - Range
 Copper Solid Size (Range)
 DLO Size (Range)
 Navy Cable Size (Range)
 Copper Stranded (Range)
 Flex (Class G) Size - Range
 Flex (Class M) Size - Range

N/A
 535.3
 535.3
 N/A
 535.3 (1325/#24)
 N/A
 500 kcmil
 535.3
 535.3

Type of Plating
 Bolt Hole Size
 Color Code
 Plated (Yes or No)
 Index Number
 Product Material

Physical

Tin - Electro Plated
 3/8
 Pink
 Y
 L99
 Copper

Approvals / Certifications

UL Listed
 CSA Certified
 ROHS Compatible
 UL Recognized
 CULUS
 Industry Standards

Y
 Y
 Compliant
 N
 N
 UL468A-468B

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
 Manchester NH03109

BURNDY Technical Servcies

47, industrial Park Drive
 Manchester NH03109

Hours: 8.00 AM - 5.00 PM
 Monday - Friday
 Phone: 000-346-4175

