




On Line Catalog

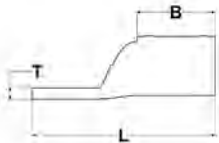

BURNDY Catalog Number
UPC Number
Description
Status

YA44LTC58FX
781810021071
CU. COMP. TERM. - 750 MC
Active

Web Use
BURNDY Product Line

Tongue Angle
Length (in)
Tongue Type
Barrell Style
Bolt Hole Size (in)
Barrel Type
Thickness
B Length (in)
Pad Width (in)
Strip Length

Dimensional

Straight
4.04
Standard
Chamfered
0.66
Standard
0.33
1.65
2.19
1-5/8

Number of Holes
Product Description

General

1
Copper Compression Lug, 1 Hole
w/ Inspection Window, 777.7 Flex,
5/8" Stud, Short Barrel, Tin Plated

Flex (Class G) Size - Range
Flex (Class H) Size - Range
Flex (Class I) Size - Range
Copper Solid Size (Range)
DLO Size (Range)
Copper Stranded (Range)

Conductor(s)

750
750
750
N/A
777.7 (1925/#24)
N/A

Type of Plating
Bolt Hole Size
Color Code
Plated (Yes or No)
Index Number
Product Material

Physical

Tin
5/8
Yellow
Y
L115
Copper

UL Listed
CSA Certified
ROHS Compatible
UL Recognized
CULUS

Approvals / Certifications

Y
Y
Compliant
N
N

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
Manchester NH03109

BURNDY Technical Servcies

47, industrial Park Drive
Manchester NH03109

Hours: 8.00 AM - 5.00 PM
Monday - Friday
Phone: 000-346-4175