




[On Line Catalog](#)



**BURNDY Catalog Number**  
**UPC Number**  
**Description**  
**Status**

YA4CL2TC14E1  
781810019641  
4STR 1/4STUD 1SPAC  
Active

**Web Use**  
BURNDY Product Line

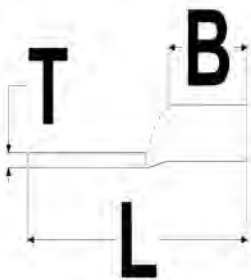

Tongue Angle  
Length (in)  
Barrell Style  
Bolt Hole Size (in)  
Barrel Type  
Thickness  
B Length (in)  
Pad Width (in)  
E - in  
Strip Length

**Dimensional**

Straight  
2.74  
Chamfered,Skived  
0.27  
Standard  
0.09  
0.81  
0.50  
1.00  
7/8

Number of Holes

**General**

2  
Cu code conductor std barrel, 2  
Holes/W/insp W, #4AWG, 600V-  
35kV, 1/4" stud, Tin plated, Grey,  
8 or 346 Index , UL Listed 90C

Product Description

**Conductor(s)**

Flex (Class G) Size - Range  
Flex (Class H) Size - Range  
Flex (Class I) Size - Range  
Copper Solid Size (Range)  
DLO Size (Range)  
Copper Stranded (Range)

N/A  
N/A  
N/A  
N/A  
N/A  
4 AWG

**Physical**

Type of Plating  
Bolt Hole Size  
Color Code  
Plated (Yes or No)  
Index Number  
Product Material

Tin - Electro Plated  
1/4  
Gray  
Y  
8,346  
Copper

**Approvals / Certifications**

UL Listed  
CSA Certified  
ROHS Compatible  
UL Recognized  
CULUS  
Industry Standards

Y  
Y  
Compliant  
N  
N  
UL468A-468B

**Documentation**

**For further technical assistance, please contact us**

**BURNDY LLC - USA**

47, industrial Park Drive  
Manchester NH03109

**BURNDY Technical Servcies**

47, industrial Park Drive  
Manchester NH03109

Hours: 8.00 AM - 5.00 PM  
Monday - Friday  
Phone: 000-346-4175