




On Line Catalog



BURNDY Catalog Number
UPC Number
Description
Status

YA8CL2TC14E2
 781810018460
 CU HYLUG-8STR-1/4X3/4C-C
 Active

Web Use
 BURNDY Product Line

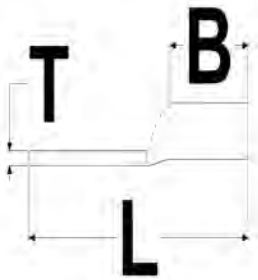

Tongue Angle
 Length (in)
 Tongue Type
 Barrell Style
 Bolt Hole Size (in)
 Barrel Type
 Thickness
 B Length (in)
 Pad Width (in)
 E - in
 Strip Length

Dimensional

Straight
 2.08
 Standard
 Chamfered
 0.27
 Standard
 0.08
 0.44
 0.44
 0.75
 7/16

Number of Holes

General

2
 Copper Compression Lug, 2 Hole
 w/ Inspection Window, 8 AWG,
 1/4" Stud, 3/4" Stud Hole
 Spacing, Short Barrel, Tin - Electro
 Plated

Product Description

Conductor(s)

Flex (Class G) Size - Range
 Flex (Class H) Size - Range
 Flex (Class I) Size - Range
 Copper Solid Size (Range)
 DLO Size (Range)
 Copper Stranded (Range)

N/A
 N/A
 N/A
 N/A
 N/A
 8 AWG

Physical

Type of Plating
 Bolt Hole Size
 Color Code
 Plated (Yes or No)
 Index Number
 Product Material

Tin - Electro Plated
 1/4
 Red
 Y
 49
 Copper

Approvals / Certifications

UL Listed
 CSA Certified
 ROHS Compatible
 UL Recognized
 CULUS
 Industry Standards

Y
 Y
 Compliant
 N
 N
 UL468A-468B

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
 Manchester NH03109

BURNDY Technical Services

47, industrial Park Drive
 Manchester NH03109

Hours: 8.00 AM - 5.00 PM
 Monday - Friday
 Phone: 000-346-4175