 





[On Line Catalog](#)

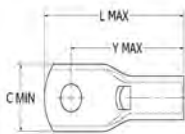

BURNDY Catalog Number
UPC Number
Description
Status

YAV10T4
781810025284
12-10 HVYDTY RING 3/8 ST
Active

Web Use
BURNDY Product Line

Length (in)
Tongue Type
Stud Size (in)
Pad Width (in)

Dimensional

1.14
Ring
3/8
0.56

Product Description

General

Copper Compression Lug, 1 Hole
w/ Inspection Window, 14-10
AWG/12-10 AWG, 3/8" Stud,
Short Barrel, Tin Plated

Aircraft Cable Size (Range)
Copper Solid Size (Range)
Navy Cable Size (Range)
Copper Stranded (Range)

Conductor(s)

N/A
12 AWG-10 AWG
N/A
12 AWG-10 AWG

Type of Plating
Connector Type
Plated (Yes or No)

Physical

Tin - Electro Plated
Terminal - Ring
Y

UL Listed
CSA Certified
ROHS Compatible
UL Recognized
Mil-Spec Class Code
CULUS

Approvals / Certifications

Y
Y
Compliant
N
Class 1, Class 2
N
UL467, Military Specified (Mil-Spec)

Industry Standards

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
Manchester NH03109

BURNDY Technical Servcies

47, industrial Park Drive
Manchester NH03109

Hours: 8.00 AM - 5.00 PM
Monday - Friday
Phone: 000-346-4175