




On Line Catalog

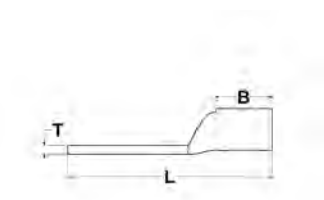

BURNDY Catalog Number
UPC Number
Description
Status

YAV1CL2TC38FX
781810022290
CU HYLUG- 1 FLEX-3/8X1
Active

Web Use
BURNDY Product Line

Tongue Angle
Length (in)
Tongue Type
Barrell Style
Bolt Hole Size (in)
Barrel Type
Thickness
B Length (in)
Pad Width (in)
E - in
Strip Length

Dimensional
Straight
2.85
Standard
Chamfered,Skived
0.39
Standard
0.12
0.62
0.75
1.00
11/16

Number of Holes

Product Description

General
2
Copper Compression Lug, 2 Hole
w/ Inspection Window, 1 Flex,
3/8" Stud, 1" Stud Hole Spacing,
Short Barrel, Tin Plated

Flex (Class G) Size - Range
Flex (Class H) Size - Range
Flex (Class I) Size - Range
Copper Solid Size (Range)
DLO Size (Range)
Copper Stranded (Range)

Conductor(s)
1 AWG
1 AWG
1 AWG
N/A
1 (225/#24) DLO
1 AWG

Type of Plating
Bolt Hole Size
Color Code
Plated (Yes or No)
Index Number
Product Material

Physical
Tin
3/8
Green
Y
11
Copper

UL Listed
CSA Certified
ROHS Compatible
UL Recognized
CULUS

Approvals / Certifications
Y
Y
Compliant
N
N

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
Manchester NH03109

BURNDY Technical Servcies

47, industrial Park Drive
Manchester NH03109

Hours: 8.00 AM - 5.00 PM
Monday - Friday
Phone: 000-346-4175