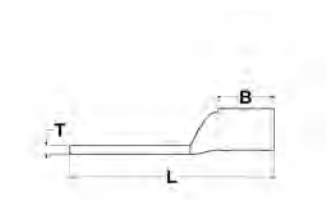



[On Line Catalog](#)


BURNDY Catalog Number
UPC Number
Description
Status

YAV25L2TC14E2FX
 781810032701
 1/0FX 1/4STUD 3/4IN CTR
 Active

Web Use
 BURNDY Product Line

Tongue Angle
 Length (in)
 Tongue Type
 Barrell Style
 Bolt Hole Size (in)
 Barrel Type
 Thickness
 B Length (in)
 Pad Width (in)
 E - in
 Strip Length

Dimensional

Straight
 2.51
 Standard
 Chamfered, Skived
 0.27
 Standard
 0.12
 0.69
 0.83
 0.75
 11/16

Number of Holes
 Product Description

General

2
 Copper Compression Lug, 2 Hole
 w/ Inspection Window, 1/0 Flex,
 1/4" Stud, 3/4" Stud Hole
 spacing, Short Barrel, Tin Plated

Flex (Class G) Size - Range
 Flex (Class H) Size - Range
 Flex (Class I) Size - Range
 Copper Solid Size (Range)
 DLO Size (Range)
 Copper Stranded (Range)

Conductor(s)

1/0 AWG
 1/0 AWG
 1/0 AWG
 N/A
 1/0 (275/#24) DLO
 1/0

Type of Plating
 Bolt Hole Size
 Color Code
 Plated (Yes or No)
 Index Number
 Product Material

Physical

Tin
 1/4
 Pink
 Y
 12
 Copper

Approvals / Certifications

UL Listed
 CSA Certified
 ROHS Compatible
 UL Recognized
 CULUS

Y
 Y
 Compliant
 N
 N

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
 Manchester NH03109

BURNDY Technical Servcies

47, industrial Park Drive
 Manchester NH03109

Hours: 8.00 AM - 5.00 PM

Monday - Friday

Phone: 000-346-4175