




On Line Catalog

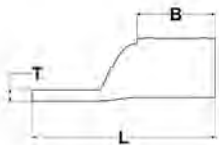

BURNDY Catalog Number
UPC Number
Description
Status

YAV25LTC12FX
781810021941
CU-TERM 1/0 FLEX-1/2 STU
Active

Web Use
BURNDY Product Line

Tongue Angle
Length (in)
Tongue Type
Barrell Style
Bolt Hole Size (in)
Barrel Type
Thickness
B Length (in)
Pad Width (in)
Strip Length

Dimensional
Straight
2.19
Standard
Chamfered
0.52
Standard
0.12
0.69
0.83
11/16

Number of Holes

Product Description

General
1
Copper Compression Lug, 1 Hole
w/ Inspection Window, 1/0 Flex,
1/2" Stud, Short Barrel, Tin Plated

Flex (Class G) Size - Range
Flex (Class H) Size - Range
Flex (Class I) Size - Range
Copper Solid Size (Range)
DLO Size (Range)
Copper Stranded (Range)

Conductor(s)
1/0 AWG
1/0 AWG
1/0 AWG
N/A
1/0 (275/#24) DLO
1/0

Type of Plating
Bolt Hole Size
Color Code
Plated (Yes or No)
Index Number
Product Material

Physical
Tin
1/2
Pink
Y
12
Copper

UL Listed
CSA Certified
ROHS Compatible
UL Recognized
CULUS

Approvals / Certifications
Y
Y
Compliant
N
N

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
Manchester NH03109

BURNDY Technical Servcies

47, industrial Park Drive
Manchester NH03109

Hours: 8.00 AM - 5.00 PM
Monday - Friday
Phone: 000-346-4175