




On Line Catalog

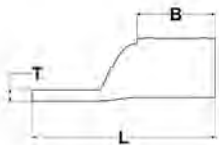

BURNDY Catalog Number
UPC Number
Description
Status

YAV25LTC516FX
781810021958
1/0FLEX 5/16STUD
Active

Web Use
BURNDY Product Line

Tongue Angle
Length (in)
Tongue Type
Barrell Style
Bolt Hole Size (in)
Barrel Type
Thickness
B Length (in)
Pad Width (in)
Strip Length

Dimensional
Straight
1.81
Standard
Chamfered
0.33
Standard
0.12
0.69
0.83
11/16

Number of Holes

General
1
Cu Comp Terminal Flex Cond, Bvl
Entry, 1 Hole/W/InspWindow, 1/0
Weld, 1/0(275/#24)DLO Flex, 1/0
AWG Code, 100 Navy, 600 V-35
kV, 5/16" Stud, Std bbl

Product Description

Flex (Class G) Size - Range
Flex (Class H) Size - Range
Flex (Class I) Size - Range
Copper Solid Size (Range)
DLO Size (Range)
Copper Stranded (Range)

Conductor(s)
1/0 AWG
1/0 AWG
1/0 AWG
N/A
1/0 (275/#24) DLO
1/0

Type of Plating
Bolt Hole Size
Color Code
Plated (Yes or No)
Index Number
Product Material

Physical
Tin
5/16
Pink
Y
12
Copper

UL Listed
CSA Certified
ROHS Compatible
UL Recognized
CULUS

Approvals / Certifications
Y
Y
Compliant
N
N

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
Manchester NH03109

BURNDY Technical Servcies

47, industrial Park Drive
Manchester NH03109

Hours: 8.00 AM - 5.00 PM
Monday - Friday
Phone: 000-346-4175