




On Line Catalog

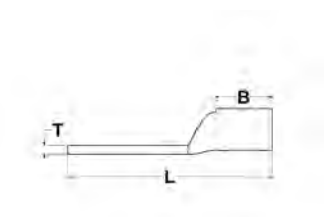

BURNDY Catalog Number
UPC Number
Description
Status

YAV26L2TC14FX
781810035733
HYDENT 2/0 AWG (2) 1/4
Active

Web Use
BURNDY Product Line

Tongue Angle
Length (in)
Barrell Style
Bolt Hole Size (in)
Barrel Type
Thickness
B Length (in)
Pad Width (in)
E - in
Strip Length

Dimensional
Straight
2.56
Chamfered,Skived
0.27
Standard
0.13
0.81
0.93
0.63
13/16

Number of Holes

Product Description

General
2
Copper Compression Lug, 2 Hole
w/ Inspection window, 2/0 Flex,
1/4" Stud, 5/8" Stud Hole
Spacing, Short Barrel, Tin Plated

Flex (Class G) Size - Range
Flex (Class H) Size - Range
Flex (Class I) Size - Range
Copper Solid Size (Range)
DLO Size (Range)
Copper Stranded (Range)

Conductor(s)
2/0 AWG
2/0 AWG
2/0 AWG
N/A
2/0 (375/#24) DLO
2/0 AWG

Type of Plating
Bolt Hole Size
Color Code
Plated (Yes or No)
Index Number
Product Material

Physical
Tin
1/4
Black
Y
13
Copper

UL Listed
CSA Certified
ROHS Compatible
UL Recognized
CULUS

Approvals / Certifications
Y
Y
Compliant
N
N

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
Manchester NH03109

BURNDY Technical Servcies

47, industrial Park Drive
Manchester NH03109

Hours: 8.00 AM - 5.00 PM
Monday - Friday
Phone: 000-346-4175