




On Line Catalog

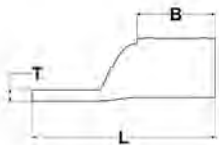

BURNDY Catalog Number
UPC Number
Description
Status

YAV27LTC516FX
781810022498
CU-HYDENT 3/0 FLEX 5/16
Active

Web Use
BURNDY Product Line

Tongue Angle
Length (in)
Barrell Style
Bolt Hole Size (in)
Barrel Type
Thickness
B Length (in)
Pad Width (in)
Strip Length

Dimensional
Straight
2.21
Chamfered
0.33
Standard
0.14
1.00
1.03
1

Number of Holes

General
1
Copper Compression Lug, 1 Hole
w/ Inspection Window, 3/0 Flex,
5/16" Stud, Short Barrel, Tin
Plated

Product Description

Flex (Class G) Size - Range
Flex (Class H) Size - Range
Flex (Class I) Size - Range
Copper Solid Size (Range)
DLO Size (Range)
Copper Stranded (Range)

Conductor(s)
3/0 AWG
3/0 AWG
3/0 AWG
N/A
3/0 (450/#24) DLO
3/0 AWG

Type of Plating
Bolt Hole Size
Color Code
Plated (Yes or No)
Index Number
Product Material

Physical
Tin - Electro Plated
5/16
Orange
Y
14
Copper

UL Listed
CSA Certified
ROHS Compatible
UL Recognized
CULUS

Approvals / Certifications
Y
Y
Compliant
N
N

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
Manchester NH03109

BURNDY Technical Servcies

47, industrial Park Drive
Manchester NH03109

Hours: 8.00 AM - 5.00 PM
Monday - Friday
Phone: 000-346-4175