




On Line Catalog

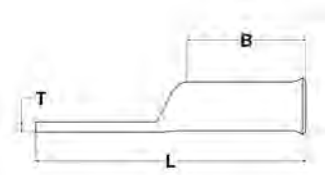

BURNDY Catalog Number
UPC Number
Description
Status

YAV282NFXB
781810046265
BELLED HYLUG-4/0 FLEX-NE
Active

Web Use
BURNDY Product Line

Tongue Angle
Length (in)
Tongue Type
Barrell Style
Bolt Hole Size (in)
Barrel Type
Thickness
B Length (in)
Pad Width (in)
E - in
Strip Length

Dimensional
Straight
5.39
Standard
Belled
Long
0.14
1.77
1.14
1.75
1-7/8

Number of Holes

General
2
Cu Comp Terminal Flex
Cond(Telecom), 2
Hole/W/O/InspWindow, 4/0
Str,4/0(550/#24)DLO,4/0 AWG
Code, 600 V-35 kV, 1/2" Stud,
1.75" Spacing, Lng bbl, Belled
End

Product Description

Aircraft Cable Size (Range)
Flex (Class H) Size - Range
Flex (Class I) Size - Range
Copper Solid Size (Range)
DLO Size (Range)
Navy Cable Size (Range)
Copper Stranded (Range)
Flex (Class G) Size - Range
Flex (Class M) Size - Range

Conductor(s)
N/A
4/0 AWG
4/0 AWG
N/A
4/0 (550/#24) DLO
N/A
4/0 AWG
4/0 AWG
4/0 AWG

Type of Plating
Bolt Hole Size
Color Code
Plated (Yes or No)
Index Number
Product Material

Physical
Tin - Electro Plated
1/2
Purple
Y
15
Copper

UL Listed
CSA Certified
ROHS Compatible
UL Recognized
CULUS

Approvals / Certifications
Y
Y
Compliant
N
N

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

BURNDY Technical Servcies

Hours: 8.00 AM - 5.00 PM
Monday - Friday
Phone: 000-346-4175

2/20/2015

Datasheet - Burndy - YAV282NFXB

47, industrial Park Drive
Manchester NH03109

47, industrial Park Drive
Manchester NH03109