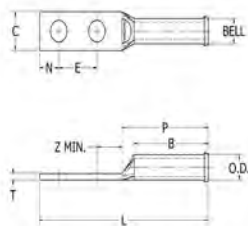



[On Line Catalog](#)


BURNDY Catalog Number
UPC Number
Description
Status

YAV282TC38FXB
 781810070574
 HYLUG-4/0 FLEX BELLED
 Active

Web Use
 BURNDY Product Line

Dimensional

Tongue Angle
 Length (in)
 Tongue Type
 Barrell Style
 Bolt Hole Size (in)
 Barrel Type
 Thickness
 B Length (in)
 Pad Width (in)
 E - in
 Strip Length

Straight
 4.20
 Standard
 Belled
 0.39
 Long
 0.14
 1.77
 1.14
 1.00
 1-7/8

General

Number of Holes

2
 Copper Compression Lug, 2 Hole
 w/o Inspection Window, 4/0 Flex,
 3/8" Stud, 1" Stud Hole Spacing,
 Short Barrel, Belled End, Tin
 Plated

Product Description

Conductor(s)

Flex (Class G) Size - Range
 Flex (Class H) Size - Range
 Flex (Class I) Size - Range
 Copper Solid Size (Range)
 DLO Size (Range)
 Copper Stranded (Range)

4/0 AWG
 4/0 AWG
 4/0 AWG
 N/A
 4/0 (550/#24) DLO
 4/0 AWG

Physical

Type of Plating
 Bolt Hole Size
 Color Code
 Plated (Yes or No)
 Index Number
 Product Material

Tin - Electro Plated
 3/8
 Purple
 Y
 15
 Copper

Approvals / Certifications

UL Listed
 CSA Certified
 ROHS Compatible
 UL Recognized
 CULUS

Y
 Y
 Compliant
 N
 N

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
 Manchester NH03109

BURNDY Technical Servcies

47, industrial Park Drive
 Manchester NH03109

Hours: 8.00 AM - 5.00 PM
 Monday - Friday
 Phone: 000-346-4175