




[On Line Catalog](#)

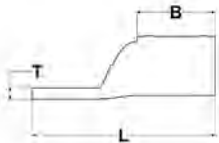

**BURNDY Catalog Number**  
**UPC Number**  
**Description**  
**Status**

YAV28LTC58FX  
781810022634  
CUHYLUG 4/0 FLEX 5/8 STU  
Active

**Web Use**  
BURNDY Product Line

Tongue Angle  
Length (in)  
Tongue Type  
Barrell Style  
Bolt Hole Size (in)  
Barrel Type  
Thickness  
B Length (in)  
Pad Width (in)  
Strip Length

**Dimensional**  
Straight  
2.92  
Standard  
Chamfered  
0.66  
Standard  
0.15  
1.03  
1.14  
1-1/16

Number of Holes

**General**  
1  
Cu Comp Terminal Flex Cond, Bvl  
Entry, 1 Hole/W/InspWindow, 4/0  
Weld, 4/0(550/#24)DLO Flex, 4/0  
AWG Code, 200 Navy, 600 V-35  
kV, 5/8" Stud, Std bbl

Product Description

Flex (Class G) Size - Range  
Flex (Class H) Size - Range  
Flex (Class I) Size - Range  
Copper Solid Size (Range)  
DLO Size (Range)  
Copper Stranded (Range)

**Conductor(s)**  
4/0 AWG  
4/0 AWG  
4/0 AWG  
N/A  
4/0 (550/#24) DLO  
4/0 AWG

Type of Plating  
Bolt Hole Size  
Color Code  
Plated (Yes or No)  
Index Number  
Product Material

**Physical**  
Tin  
5/8  
Purple  
Y  
15  
Copper

UL Listed  
CSA Certified  
ROHS Compatible  
UL Recognized  
CULUS

**Approvals / Certifications**  
Y  
Y  
Compliant  
N  
N

**Documentation**

For further technical assistance, please contact us

**BURNDY LLC - USA**

47, industrial Park Drive  
Manchester NH03109

**BURNDY Technical Servcies**

47, industrial Park Drive  
Manchester NH03109

Hours: 8.00 AM - 5.00 PM  
Monday - Friday  
Phone: 000-346-4175