




On Line Catalog

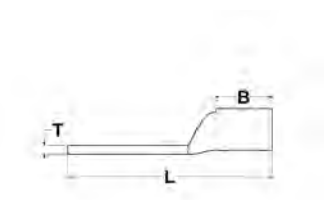

**BURNDY Catalog Number**  
**UPC Number**  
**Description**  
**Status**

YAV2CL2TC14E2FX  
781810022238  
CULUG-2FLX-1/4STDX3/4C-C  
Active

**Web Use**  
BURNDY Product Line

Tongue Angle  
Length (in)  
Tongue Type  
Barrell Style  
Bolt Hole Size (in)  
Barrel Type  
Thickness  
B Length (in)  
Pad Width (in)  
E - in  
Strip Length

**Dimensional**

Straight  
2.38  
Standard  
Chamfered  
0.27  
Standard  
0.10  
0.63  
0.68  
0.75  
11/16

Number of Holes

**General**

2  
Copper Compression Lug, 2 Hole  
w/ Inspection Window, 2 Flex,  
1/4" Stud, 3/4" Stud Hole  
Spacing, Short Barrel, Tin Plated

Product Description

**Conductor(s)**

Flex (Class G) Size - Range  
Flex (Class H) Size - Range  
Flex (Class I) Size - Range  
Copper Solid Size (Range)  
DLO Size (Range)  
Copper Stranded (Range)

2 AWG  
2 AWG  
2 AWG  
2 AWG  
3 (125/#24) DLO-2 (150/#24) DLO  
2 AWG

**Physical**

Type of Plating  
Bolt Hole Size  
Color Code  
Plated (Yes or No)  
Index Number  
Product Material

Tin - Electro Plated  
1/4  
Brown  
Y  
10  
Copper

**Approvals / Certifications**

UL Listed  
CSA Certified  
ROHS Compatible  
UL Recognized  
CULUS

Y  
Y  
Compliant  
N  
N

**Documentation**

**For further technical assistance, please contact us**

**BURNDY LLC - USA**

47, industrial Park Drive  
Manchester NH03109

**BURNDY Technical Servcies**

47, industrial Park Drive  
Manchester NH03109

Hours: 8.00 AM - 5.00 PM  
Monday - Friday  
Phone: 000-346-4175