




On Line Catalog

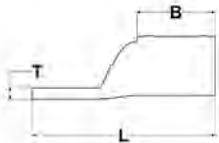

**BURNDY Catalog Number**  
**UPC Number**  
**Description**  
**Status**

YAV2CLTC12FX  
781810022795  
2FLEX 1/2 STUD  
Active

**Web Use**  
BURNDY Product Line

Tongue Angle  
Length (in)  
Tongue Type  
Barrell Style  
Bolt Hole Size (in)  
Barrel Type  
Thickness  
B Length (in)  
Pad Width (in)  
Strip Length

**Dimensional**  
Straight  
2.12  
Standard  
Chamfered  
0.52  
Standard  
0.09  
0.63  
0.73  
11/16

Number of Holes

**General**  
1  
Cu Comp Terminal Flex Cond, Bvl  
Entry, 1 Hole/W/InspWindow, #2  
Weld, 3(125/#24)-2(150/#24)DLO  
Flex, #2 AWG Code, 60 Navy, 600  
V-35 kV, 1/2" Stud, Std bbl

Product Description

Flex (Class G) Size - Range  
Flex (Class H) Size - Range  
Flex (Class I) Size - Range  
Copper Solid Size (Range)  
DLO Size (Range)  
Copper Stranded (Range)

**Conductor(s)**  
2 AWG  
2 AWG  
2 AWG  
2 AWG  
3 (125/#24) DLO-2 (150/#24) DLO  
2 AWG

Type of Plating  
Bolt Hole Size  
Color Code  
Plated (Yes or No)  
Index Number  
Product Material

**Physical**  
Tin - Electro Plated  
1/2  
Brown  
Y  
10  
Copper

UL Listed  
CSA Certified  
ROHS Compatible  
UL Recognized  
CULUS

**Approvals / Certifications**  
Y  
Y  
Compliant  
N  
N

**Documentation**

**For further technical assistance, please contact us**

**BURNDY LLC - USA**

47, industrial Park Drive  
Manchester NH03109

**BURNDY Technical Servcies**

47, industrial Park Drive  
Manchester NH03109

Hours: 8.00 AM - 5.00 PM  
Monday - Friday  
Phone: 000-346-4175