




On Line Catalog

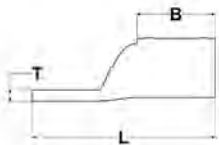

BURNDY Catalog Number
UPC Number
Description
Status

YAV2CLTC516FX
781810022412
CUHYLUG- 2 STR FLEX-5/16
Active

Web Use
BURNDY Product Line

Tongue Angle
Length (in)
Tongue Type
Barrell Style
Bolt Hole Size (in)
Barrel Type
Thickness
B Length (in)
Pad Width (in)
Strip Length

Dimensional
Straight
1.69
Standard
Chamfered
0.33
Standard
0.10
0.63
0.68
11/16

Number of Holes

General
1
Copper Compression Lug, 1 Hole
w/ Inspection Window, 2 Flex,
5/16" Stud, Short Barrel, Tin
Plated

Product Description

Flex (Class G) Size - Range
Flex (Class H) Size - Range
Flex (Class I) Size - Range
Copper Solid Size (Range)
DLO Size (Range)
Copper Stranded (Range)

Conductor(s)
2 AWG
2 AWG
2 AWG
2 AWG
3 (125/#24) DLO-2 (150/#24) DLO
2 AWG

Type of Plating
Bolt Hole Size
Color Code
Plated (Yes or No)
Index Number
Product Material

Physical
Tin - Electro Plated
5/16
Brown
Y
10
Copper

UL Listed
CSA Certified
ROHS Compatible
UL Recognized
CULUS

Approvals / Certifications
Y
Y
Compliant
N
N

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
Manchester NH03109

BURNDY Technical Servcies

47, industrial Park Drive
Manchester NH03109

Hours: 8.00 AM - 5.00 PM
Monday - Friday
Phone: 000-346-4175