




[On Line Catalog](#)

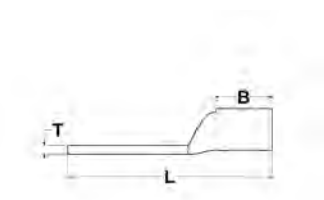

BURNDY Catalog Number
UPC Number
Description
Status

YAV4CL2TC14E2FX
781810022184
CUHYLUG 4STRFLEX 2) 1/4
Active

Web Use
BURNDY Product Line

Tongue Angle
Length (in)
Tongue Type
Barrell Style
Bolt Hole Size (in)
Barrel Type
Thickness
B Length (in)
Pad Width (in)
E - in
Strip Length

Dimensional

Straight
2.20
Standard
Chamfered
0.27
Standard
0.09
0.50
0.55
0.75
9/16

Number of Holes

Product Description

General

2
Copper Compression Lug, 2 Hole
w/ Inspection Window, 4 Flex,
1/4" Stud, 3/4" Stud Hole
Spacing, Short Barrel, Tin Plated

Flex (Class G) Size - Range
Flex (Class H) Size - Range
Flex (Class I) Size - Range
Copper Solid Size (Range)
DLO Size (Range)
Copper Stranded (Range)

Conductor(s)

4 AWG
4 AWG
4 AWG
4 AWG
5 (91/#24) DLO-4 (105/#24) DLO
4 AWG

Type of Plating
Bolt Hole Size
Color Code
Plated (Yes or No)
Index Number
Product Material

Physical

Tin - Electro Plated
1/4
Gray
Y
8
Copper

UL Listed
CSA Certified
ROHS Compatible
UL Recognized
CULUS

Approvals / Certifications

Y
Y
Compliant
N
N

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
Manchester NH03109

BURNDY Technical Servcies

47, industrial Park Drive
Manchester NH03109

Hours: 8.00 AM - 5.00 PM
Monday - Friday
Phone: 000-346-4175