




On Line Catalog

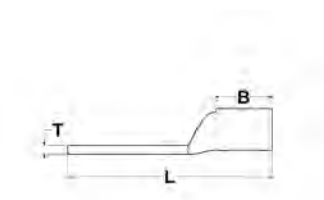

BURNDY Catalog Number
UPC Number
Description
Status

YAV4CL2TC38FX
781810022191
CUHYLUG 4STRFLEX 2)3/8 4
Active

Web Use
BURNDY Product Line

Tongue Angle
Length (in)
Tongue Type
Barrell Style
Bolt Hole Size (in)
Barrel Type
Thickness
B Length (in)
Pad Width (in)
E - in
Strip Length

Dimensional
Straight
2.68
Standard
Chamfered
0.39
Standard
0.08
0.50
0.58
1.00
9/16

Number of Holes

Product Description

General
2
Copper Compression Lug, 2 Hole
w/ Inspection Window, 4 Flex,
3/8" Stud, 1" Stud Hole Spacing,
Short Barrel, Tin Plated

Flex (Class G) Size - Range
Flex (Class H) Size - Range
Flex (Class I) Size - Range
Copper Solid Size (Range)
DLO Size (Range)
Copper Stranded (Range)

Conductor(s)
4 AWG
4 AWG
4 AWG
4 AWG
5 (91/#24) DLO-4 (105/#24) DLO
4 AWG

Type of Plating
Bolt Hole Size
Color Code
Plated (Yes or No)
Index Number
Product Material

Physical
Tin - Electro Plated
3/8
Gray
Y
8
Copper

UL Listed
CSA Certified
ROHS Compatible
UL Recognized
CULUS

Approvals / Certifications
Y
Y
Compliant
N
N

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
Manchester NH03109

BURNDY Technical Servcies

47, industrial Park Drive
Manchester NH03109

Hours: 8.00 AM - 5.00 PM
Monday - Friday
Phone: 000-346-4175