




On Line Catalog

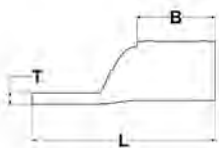

BURNDY Catalog Number
UPC Number
Description
Status

YAV4CLTC10FX
781810022610
CU HYLUG 4 STR FLEX 10
Active

Web Use
BURNDY Product Line

Tongue Angle
Length (in)
Tongue Type
Barrell Style
Bolt Hole Size (in)
Barrel Type
Thickness
B Length (in)
Pad Width (in)
Strip Length

Dimensional
Straight
1.32
Standard
Chamfered
0.20
Standard
0.09
0.50
0.55
1/2

Number of Holes

General
1
Cu Tubing Hylug; 1 Hole with Inspection Window; #4 WELD, 5(91/#24)-4(105/#24) DLO, #4 AWG Code, 40 & 50 Navy; 600V-35kV; #10 stud; Compression; 0.21 in BCD

Product Description

Conductor(s)
4 AWG
4 AWG
4 AWG
4 AWG
5 (91/#24) DLO-4 (105/#24) DLO
4 AWG

Flex (Class G) Size - Range
Flex (Class H) Size - Range
Flex (Class I) Size - Range
Copper Solid Size (Range)
DLO Size (Range)
Copper Stranded (Range)

Physical
Tin - Electro Plated
#10
Gray
Y
8
Copper

Type of Plating
Bolt Hole Size
Color Code
Plated (Yes or No)
Index Number
Product Material

Approvals / Certifications

UL Listed
CSA Certified
ROHS Compatible
UL Recognized
CULUS

Y
Y
Compliant
N
N

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
Manchester NH03109

BURNDY Technical Servcies

47, industrial Park Drive
Manchester NH03109

Hours: 8.00 AM - 5.00 PM
Monday - Friday
Phone: 000-346-4175