




On Line Catalog

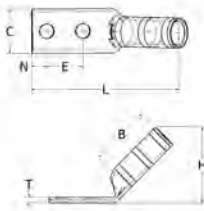

BURNDY Catalog Number
UPC Number
Description
Status

YAV6CL2TC14FX45
781810022894
CUHYLUG- 6FLEX-(2)1/4ST-
Active

Web Use
BURNDY Product Line

Tongue Angle
Length (in)
Tongue Type
Barrell Style
Bolt Hole Size (in)
Barrel Type
Thickness
B Length (in)
Pad Width (in)
E - in
Strip Length

Dimensional
45 Degree
2.02
Standard
Chamfered
0.27
Standard
0.08
0.50
0.48
0.63
9/16

Number of Holes

General
2
Cu Comp Terminal Flex Cond, 2
Hole/W/InspWindow, #6 Weld,
6(61/#24)DLO Flex, #6 AWG
Code, 30 Navy, 600 V-35 kV, 1/4"
Stud, 0.63" Spacing, 45 Bent, Std
bbl

Product Description

Flex (Class G) Size - Range
Flex (Class H) Size - Range
Flex (Class I) Size - Range
Copper Solid Size (Range)
DLO Size (Range)
Copper Stranded (Range)

Conductor(s)
6 AWG
6 AWG
6 AWG
6 AWG
6 (61/#24) DLO
6 AWG

Type of Plating
Bolt Hole Size
Color Code
Plated (Yes or No)
Index Number
Product Material

Physical
Tin - Electro Plated
1/4
Blue
Y
7
Copper

UL Listed
CSA Certified
ROHS Compatible
UL Recognized
CULUS

Approvals / Certifications
Y
Y
Compliant
N
N

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

BURNDY Technical Servcies

Hours: 8.00 AM - 5.00 PM
Monday - Friday
Phone: 000-346-4175

47, industrial Park Drive
Manchester NH03109

47, industrial Park Drive
Manchester NH03109