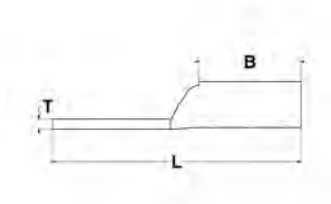



[On Line Catalog](#)


BURNDY Catalog Number
UPC Number
Description
Status

YAZ252N
 781810208564
 1/0 CU-LONG-OPEN-2 NEMA
 Active

Web Use
 BURNDY Product Line

Tongue Angle
 Length (in)
 Barrell Style
 Bolt Hole Size (in)
 Barrel Type
 Thickness
 B Length (in)
 Pad Width (in)
 E - in
 Strip Length

Dimensional

Straight
 4.79
 Skived
 0.52
 Long
 0.11
 1.38
 0.83
 1.75
 1-7/16

Number of Holes

General

2
 Cu Comp Terminal Code Cond, Bvl
 Entry, 2 Hole/W/InspWindow, 1/0
 AWG Code, 100 Navy, 600 V-35
 kV, 1/2" Stud, 1.75" Spacing, Lng
 bbl, Pink, 12 or 348 Index

Product Description

Conductor(s)

Copper Solid Size (Range)
 Navy Cable Size (Range)
 Copper Stranded (Range)

N/A
 100 (61) Navy
 1/0

Physical

Type of Plating
 Bolt Hole Size
 Color Code
 Plated (Yes or No)
 Index Number
 Product Material

Tin - Electro Plated
 1/2
 Pink
 Y
 12,348
 Copper

Approvals / Certifications

UL Listed
 CSA Certified
 ROHS Compatible
 UL Recognized
 CULUS
 Industry Standards

Y
 Y
 Compliant
 N
 N
 UL468A-468B

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
 Manchester NH03109

BURNDY Technical Servcies

47, industrial Park Drive
 Manchester NH03109

Hours: 8.00 AM - 5.00 PM
 Monday - Friday
 Phone: 000-346-4175