




On Line Catalog

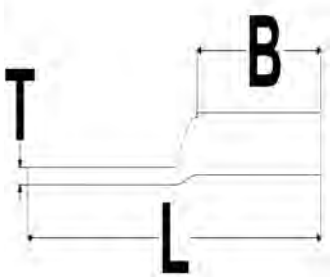

BURNDY Catalog Number
UPC Number
Description
Status

YAZ252TC14E1
781810197059
CULUG-1/0STR-LONG W/PORT
Active

Web Use
BURNDY Product Line

Tongue Angle
Length (in)
Tongue Type
Barrell Style
Bolt Hole Size (in)
Barrel Type
Thickness
B Length (in)
Pad Width (in)
E - in
Strip Length

Dimensional
Straight
3.41
Standard
Skived
0.27
Long
0.12
1.38
0.75
1.00
1-7/16

Number of Holes

General
2
Copper Compression Lug, 2 Hole
w/ Inspection Window, 1/0 AWG,
1/4" Stud, 1" Stud Hole Spacing,
Long Barrel, Tin Plated

Product Description

Copper Solid Size (Range)
Navy Cable Size (Range)
Copper Stranded (Range)

Conductor(s)
N/A
100 (61) Navy
1/0

Type of Plating
Bolt Hole Size
Color Code
Plated (Yes or No)
Index Number
Product Material

Physical
Tin - Electro Plated
1/4
Pink
Y
12,348
Copper

UL Listed
CSA Certified
ROHS Compatible
UL Recognized
CULUS

Approvals / Certifications
Y
Y
Compliant
N
N

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
Manchester NH03109

BURNDY Technical Servcies

47, industrial Park Drive
Manchester NH03109

Hours: 8.00 AM - 5.00 PM
Monday - Friday
Phone: 000-346-4175