




On Line Catalog

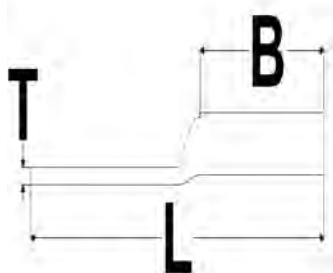

BURNDY Catalog Number
UPC Number
Description
Status

YAZ262TC14E2
 781810227848
 CULUG-2/0STR-LONG W/PORT
 Active

Web Use
 BURNDY Product Line

Tongue Angle
 Length (in)
 Tongue Type
 Barrell Style
 Bolt Hole Size (in)
 Barrel Type
 Thickness
 B Length (in)
 Pad Width (in)
 E - in
 Strip Length

Dimensional

Straight
 3.32
 Standard
 Skived
 0.27
 Long
 0.12
 1.50
 0.83
 0.75
 1-9/16

Number of Holes

General

2
 Cu Tubing Hylug; 2 Holes with
 Inspection Window; 2/0 AWG
 Code,125 Navy; 600V-35kV; 1/4"
 stud; Long; Compression; 0.27 in
 BCD; Black

Product Description

Conductor(s)

Copper Solid Size (Range)
 Navy Cable Size (Range)
 Copper Stranded (Range)

2/0 AWG
 125 (61) Navy
 2/0 AWG

Physical

Type of Plating
 Bolt Hole Size
 Color Code
 Plated (Yes or No)
 Index Number
 Product Material

Tin - Electro Plated
 1/4
 Black
 Y
 13
 Copper

Approvals / Certifications

UL Listed
 CSA Certified
 ROHS Compatible
 UL Recognized
 CULUS

Y
 Y
 Compliant
 N
 N

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
 Manchester NH03109

BURNDY Technical Servcies

47, industrial Park Drive
 Manchester NH03109

Hours: 8.00 AM - 5.00 PM
 Monday - Friday
 Phone: 000-346-4175