




On Line Catalog

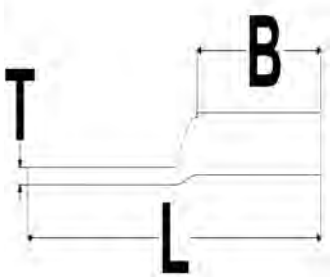

BURNDY Catalog Number
UPC Number
Description
Status

YAZ272TC38
781810216170
3/0 CU-LONG-OPEN-3/8X1
Active

Web Use
BURNDY Product Line

Tongue Angle
Length (in)
Tongue Type
Barrell Style
Bolt Hole Size (in)
Barrel Type
Thickness
B Length (in)
Pad Width (in)
E - in
Strip Length

Dimensional
Straight
3.80
Standard
Skived
0.39
Long
0.12
1.50
0.90
1.00
1-9/16

Number of Holes

General
2
Cu Tubing Hylug; 2 Holes with
Inspection Window; 3/0 AWG
Code,150 Navy; 600V-35kV; 3/8"
stud; Long; Compression; 0.40 in
BCD; Orange

Product Description

Copper Solid Size (Range)
Navy Cable Size (Range)
Copper Stranded (Range)

Conductor(s)
3/0 AWG
150 (61) Navy
3/0 AWG

Type of Plating
Bolt Hole Size
Color Code
Plated (Yes or No)
Index Number
Product Material

Physical
Tin - Electro Plated
3/8
Orange
Y
14
Copper

UL Listed
CSA Certified
ROHS Compatible
UL Recognized
CULUS

Approvals / Certifications
Y
Y
Compliant
N
N

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
Manchester NH03109

BURNDY Technical Servcies

47, industrial Park Drive
Manchester NH03109

Hours: 8.00 AM - 5.00 PM
Monday - Friday
Phone: 000-346-4175