




On Line Catalog

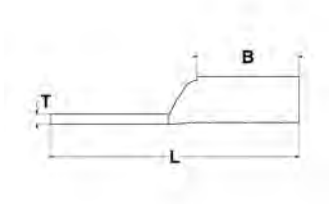

BURNDY Catalog Number
UPC Number
Description
Status

YAZ282N
781810208595
4/0 CU-LONG-OPEN-2 NEMA
Active

Web Use
BURNDY Product Line

Tongue Angle
Length (in)
Barrell Style
Bolt Hole Size (in)
Barrel Type
Thickness
B Length (in)
Pad Width (in)
E - in
Strip Length

Dimensional
Straight
5.15
Skived
0.52
Long
0.14
1.62
1.02
1.75
1-11/16

Number of Holes

Product Description

General
2
Copper Compression Lug, 2 Hole
w/ Inspection Window, 4/0 AWG,
1/2" Stud, 1-3/4" Stud Hole
Spacing, Long Barrel, Tin Plated

Copper Solid Size (Range)
Navy Cable Size (Range)
Copper Stranded (Range)

Conductor(s)
N/A
200 (61) Navy
4/0 AWG

Type of Plating
Bolt Hole Size
Color Code
Plated (Yes or No)
Index Number
Product Material

Physical
Tin - Electro Plated
1/2
Purple
Y
15
Copper

UL Listed
CSA Certified
ROHS Compatible
UL Recognized
CULUS
Industry Standards

Approvals / Certifications
Y
Y
Compliant
N
N
UL468A-468B

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
Manchester NH03109

BURNDY Technical Servcies

47, industrial Park Drive
Manchester NH03109

Hours: 8.00 AM - 5.00 PM
Monday - Friday
Phone: 000-346-4175