




[On Line Catalog](#)

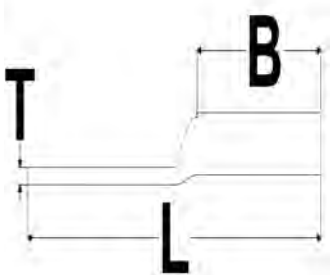

BURNDY Catalog Number
UPC Number
Description
Status

YAZ4C2TC14E2
781810227640
CULUG- 4AWG-LONG W/PORT
Active

Web Use
BURNDY Product Line

Tongue Angle
Length (in)
Barrell Style
Bolt Hole Size (in)
Barrel Type
Thickness
B Length (in)
Pad Width (in)
E - in
Strip Length

Dimensional

Straight
2.80
Skived
0.27
Long
0.09
1.12
0.50
0.75
1-3/16

Number of Holes

General

2
Cu Comp Terminal Code Cond, Bvl
Entry, 2 Hole/W/InspWindow, #4
AWG Code, 40 Navy, 600 V-35
kV, 1/4" Stud, 0.75" Spacing, Lng
bbl, Gray, 8 or 346 Index

Product Description

Conductor(s)

Copper Solid Size (Range)
Navy Cable Size (Range)
Copper Stranded (Range)

N/A
40 (19) Navy
4 AWG

Physical

Type of Plating
Bolt Hole Size
Color Code
Plated (Yes or No)
Index Number
Product Material

Tin - Electro Plated
1/4
Gray
Y
8,346
Copper

Approvals / Certifications

UL Listed
CSA Certified
ROHS Compatible
UL Recognized
CULUS

Y
Y
Compliant
N
N

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
Manchester NH03109

BURNDY Technical Servcies

47, industrial Park Drive
Manchester NH03109

Hours: 8.00 AM - 5.00 PM
Monday - Friday
Phone: 000-346-4175