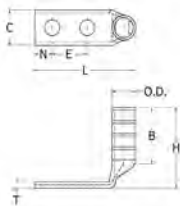



[On Line Catalog](#)


BURNDY Catalog Number
UPC Number
Description
Status

YAZ6C2TC14E290
 781810228876
 CULUG- 6AWG-LONG W/PORT
 Active

Web Use
 BURNDY Product Line

Dimensional

Tongue Angle 90 Degree
 Length (in) 1.63
 Tongue Type Standard
 Barrell Style Skived
 Bolt Hole Size (in) 0.27
 Barrel Type Long
 Thickness 0.08
 B Length (in) 1.12
 Pad Width (in) 0.45
 E - in 0.75
 Strip Length 1-3/16

General

Number of Holes 2
 Cu Tubing Hylug; 2 Holes with
 Inspection Window; #6 AWG
 Code,30 Navy; 600V-35kV; 1/4"
 stud; Long; Compression; 0.27 in
 BCD; Blue

Conductor(s)

Copper Solid Size (Range) N/A
 Navy Cable Size (Range) 30 (19) Navy
 Copper Stranded (Range) 6 AWG

Physical

Type of Plating Tin - Electro Plated
 Bolt Hole Size 1/4
 Color Code Blue
 Plated (Yes or No) Y
 Index Number 7,374
 Product Material Copper

Approvals / Certifications

UL Listed Y
 CSA Certified Y
 ROHS Compatible Compliant
 UL Recognized N
 CULUS N

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
 Manchester NH03109

BURNDY Technical Servcies

47, industrial Park Drive
 Manchester NH03109

Hours: 8.00 AM - 5.00 PM
 Monday - Friday
 Phone: 000-346-4175