




On Line Catalog

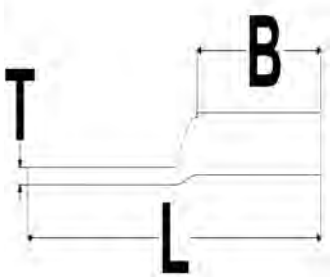

BURNDY Catalog Number
UPC Number
Description
Status

YAZ6C2TC38
781810224298
CULUG- 6STR-LONG W/PORT
Active

Web Use
BURNDY Product Line

Tongue Angle
Length (in)
Tongue Type
Barrell Style
Bolt Hole Size (in)
Barrel Type
Thickness
B Length (in)
Pad Width (in)
E - in
Strip Length

Dimensional
Straight
3.22
Standard
Skived
0.39
Long
0.06
1.12
0.58
1.00
1-3/16

Number of Holes

General
2
CU Compression Terminal Code
Conductor, Beveled Entry, 2
Hole/W/InspWindow,
#6AWG(Code) 30(Navy), 600V-
35kV, 3/8" Stud, 1" Spacing, Lng
bbl, Electro-Tin Plated

Product Description

Conductor(s)
N/A
30 (19) Navy
6 AWG

Copper Solid Size (Range)
Navy Cable Size (Range)
Copper Stranded (Range)

Physical
Tin - Electro Plated
3/8
Blue
Y
7
Copper

Type of Plating
Bolt Hole Size
Color Code
Plated (Yes or No)
Index Number
Product Material

Approvals / Certifications

UL Listed
CSA Certified
ROHS Compatible
UL Recognized
CULUS

Y
Y
Compliant
N
N

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
Manchester NH03109

BURNDY Technical Servcies

47, industrial Park Drive
Manchester NH03109

Hours: 8.00 AM - 5.00 PM
Monday - Friday
Phone: 000-346-4175