




On Line Catalog

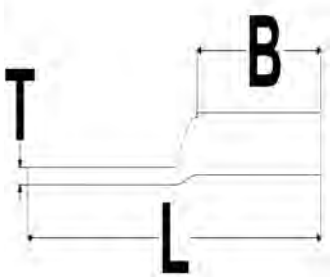

BURNDY Catalog Number
UPC Number
Description
Status

YAZ8C2TC38
781810227589
CULUG- 8AWG-LONG W/PORT
Active

Web Use
BURNDY Product Line

Tongue Angle
Length (in)
Tongue Type
Barrell Style
Bolt Hole Size (in)
Barrel Type
Thickness
B Length (in)
Pad Width (in)
E - in
Strip Length

Dimensional

Straight
2.76
Standard
Skived
0.39
Long
0.06
0.75
0.58
1.00
7/8

Number of Holes

General

2
Cu Comp Terminal Code Cond, Bvl
Entry, 2 Hole/W/InspWindow, #8
AWG Str Code, 23 Navy, 600 V-35
kV, 3/8" Stud, 1.00" Spacing, Lng
bbl, Red, 49 Index

Product Description

Conductor(s)

Copper Solid Size (Range)
Navy Cable Size (Range)
Copper Stranded (Range)

N/A
23 (7) Navy
8 AWG

Physical

Type of Plating
Bolt Hole Size
Color Code
Plated (Yes or No)
Index Number
Product Material

Tin - Electro Plated
3/8
Red
Y
49
Copper

Approvals / Certifications

UL Listed
CSA Certified
ROHS Compatible
UL Recognized
CULUS

Y
Y
Compliant
N
N

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
Manchester NH03109

BURNDY Technical Servcies

47, industrial Park Drive
Manchester NH03109

Hours: 8.00 AM - 5.00 PM
Monday - Friday
Phone: 000-346-4175