



[On Line Catalog](#)



BURNDY Catalog Number
UPC Number
Description
Status

YS31L
781810508350
HYLINK SPLICE 350 kcmil
Active

Web Use
BURNDY Product Line

Strip Length
Barrell Style
Barrel Type

Dimensional

1-3/16
Chamfered
Standard

General

Compression CU Reducer/Splice,
Barrel A:350kcmil(Str) Barrel
B:350kcmil(Str), 600V-35kV,
Standard Barrel, Electro-Tin Plated

Physical

Tin - Electro Plated
Y
18,324
Copper

Approvals / Certifications


Y
Y
Compliant
N
N
UL468A-468B

Product Description

Type of Plating
Plated (Yes or No)
Index Number
Product Material

UL Listed
CSA Certified
ROHS Compatible
UL Recognized
CULUS
Industry Standards

Documentation

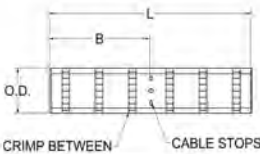

For further technical assistance, please contact us

BURNDY LLC - USA

47, industrial Park Drive
Manchester NH03109

BURNDY Technical Servcies

47, industrial Park Drive
Manchester NH03109

Hours: 8.00 AM - 5.00 PM
Monday - Friday
Phone: 000-346-4175